



GN 420 → Page 316


 GN 421 → Page 317
 GN 421.10 → Page 319
 GN 421.11 → Page 320
 GN 421.12 → Page 320

 DIN 464 → Page 326 / 327
 M6 ... M10

 DIN 466 → Page 325
 M6 ... M12


GN 534 → Page 312



GN 534 → Page 313


 GN 633 → Page XYZ
 GN 633.1 → Page XYZ

 GN 634 → Page XYZ
 GN 634.1 → Page XYZ


GN 5334 → Page 288



GN 5334 → Page 289


 GN 5337.2 → Page 284
 Size 32 ... 74

 GN 5337.2 → Page 285
 Size 32 ... 74


GN 5337.4 → Page XYZ



GN 5337.4 → Page XYZ


 DIN 6335 → Page 292 / 293
 KT / GG / AL / NI
 Size 32 ... 63

 GN 6335.4 → Page 296
 GN 6335.5 → Page 297
 ST

 DIN 6336* → Page 274 / 275
 KT/GG/AL/NI
 Size 32 ... 63

 GN 6336.4* → Page 278
 GN 6336.5 → Page 279
 ST
 Size 32 ... 63

 GN 6336.10 → Page 282
 GN 6336.11 → Page 283


GN 6336.3 → Page 281

* see also GN 6336.13 (with mounted loss protection) → New production




Specification

Recess for retaining rings and retaining rings GN 111.6 (Stainless Steel) according standard sheet

→ Page 965

The retaining rings are to be mounted in direction as shown in the drawing

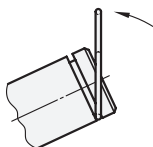

Information

The standards listed can be delivered with loss protection GN 111.7 with a recess and a retaining ring.

The retaining rings are delivered unassembled, as disassembly can lead to their deformation.

Ball chains / Retaining cables are to be ordered separately.

see also...

- Star knobs GN 6336.13 (with mounted loss protection) → New products
- Ball chains GN 111 → Page 477
- Stainless Steel-Ball chains GN 111.5 → Page 477
- Stainless Steel-Retaining cables GN 111.2 → Page 478
- Spiral retaining cables GN 111.4 → Page 479

How to order

Knurled thumb screw GN 421-M5-20
with loss protection (recess with retaining ring) **GN 111.7**

